



Job Name/Title: _____ Catalog Number _____

Contractor: _____ Notes: _____

LED Compact Wall Pack CCT SELECTABLE



Topaz's LED Compact Wall Packs provide uniform and efficient lighting. Featuring a CCT selectable switch, these outdoor luminaires are ideal for a variety of applications including stairwells, pathways and entryways in commercial and residential settings. An energy-saving and long-life alternative to traditional light sources, these wall packs deliver incredible efficiency without sacrificing performance. Rated for 50,000 hours of functional life and constructed of rugged die-cast aluminum with a high impact polycarbonate lens, these wall packs are designed to withstand the demands of all weather conditions.

FEATURES

- 3 CCT Selectable switch: 3000K, 4000K, 5000K
- Integrated dusk-to-dawn photocell
- Aluminum housing with diffused polycarbonate lens
- Bronze or white finishes available
- Suitable for up to 15-foot mounting applications

SUGGESTED APPLICATIONS

- Outdoor commercial and residential
- Entryways
- Stairwells
- Hallways
- Security lighting





Job Name/Title: _____ Catalog Number _____

Contractor: _____ Notes: _____

LED Compact Wall Pack CCT SELECTABLE

GENERAL SPECIFICATIONS

Input Voltage, Frequency: 120-277V, 50/60Hz
Power Factor, THD %: >0.9, ≤20%
Dimmable: 0-10V
Photocells Included: Yes
Efficacy: 125 LPW
CRI: 80

BUG Rating: B1U3G1 (15W, 20W)
 B1U5G1 (30W)
Functional Life (L70): 50,000 Hours
Location Rating: Wet
IP Rating: IP65
Ambient Operating Temperature: -40°F to 113°F

ITEM SPECIFICATIONS / ORDER INFO

Catalog Number	Order Code	UPC	Lumens	Wattage	Input Current 120/277V	CCT	Beam Angle	DLC ID
F-WPC/15W/CTS/BZ-96	71027	751338036833	1,875	15W	0.15/0.05A	3000K 4000K 5000K	100°	PLH8AMRJHJE9
F-WPC/15W/CTS/WH-96	71028	751338036840	1,875	15W	0.15/0.05A	3000K 4000K 5000K	100°	PLH8AMRJHJE9
F-WPC/20W/CTS/BZ-96	71029	751338036857	2,500	20W	0.26/0.065A	3000K 4000K 5000K	100°	PLTJ4XSSIQQN
F-WPC/20W/CTS/WH-96	71030	751338036864	2,500	20W	0.26/0.065A	3000K 4000K 5000K	100°	PLTJ4XSSIQQN
F-WPC/30W/CTS/BZ-96	71031	751338036871	3,750	30W	0.33/0.1A	3000K 4000K 5000K	100°	PLIV3ZGVVSZKE
F-WPC/30W/CTS/WH-96	71032	751338036888	3,750	30W	0.33/0.1A	3000K 4000K 5000K	100°	PLIV3ZGVVSZKE

NOMENCLATURE

Example: **F-WPC/15W/CTS/BZ**


F = Fixture / **WPC** = Wall Pack Compact / **15W** = 15 Watts / **CTS** = Color Temperature Selectable / **BZ** = Bronze Finish
 / **20W** = 20 Watts / **WH** = White Finish
 / **30W** = 30 Watts

ENERGY SAVINGS

Catalog Number	LED Wattage	Incandescent Replacement Wattage	Watts Saved	Yearly Savings	5 Year Savings
Based on 12 hours/day and \$0.11/kWh					
F-WPC/15W/CTS/xx-96	15W	150W	135W	\$65	\$325
F-WPC/20W/CTS/xx-96	20W	200W	180W	\$87	\$434
F-WPC/30W/CTS/xx-96	30W	300W	270W	\$130	\$650

PRODUCT DIMENSIONS / LINE DRAWINGS

Catalog Number	(A)	(B)	(C)	Weight
F-WPC/xxW/CTS/xx-96	5.79"	8.58"	3.07"	1.98 Lbs.

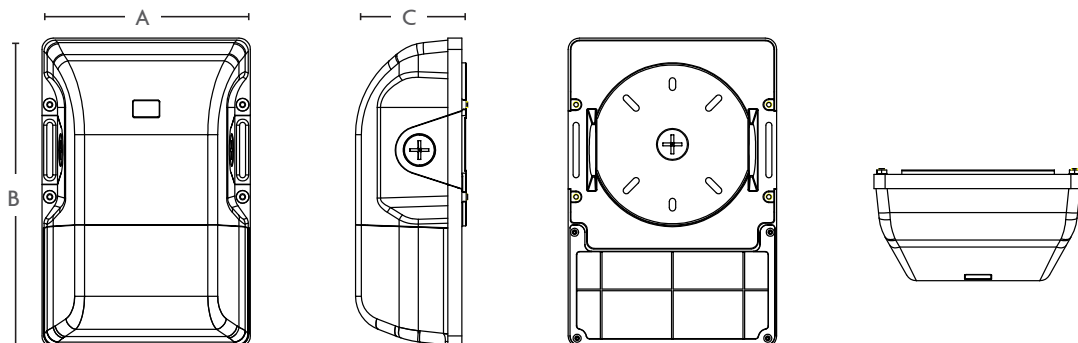

NOTES:

Specifications subject to change without prior notice. Replacement wattage shown depends on application and fixture.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Dimming with standard 0-10V control system or wall dimmers such as Leviton IP710, DS710 or Lutron DVSTV.

Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

WARNING: Some products included in this specification sheet may be subject to the warning requirements of California's Proposition 65. Please refer to your product packaging for more information.

September 2020