



Southwire®

41210S

CIRCUIT BREAKER FINDER WITH GFCI

The circuit breaker finder pinpoints the specific breaker powering the circuit being worked on. Eliminates guessing and unwanted power outages caused by tripping the wrong breaker.



RECEIVER

Receiver pinpoints signal from transmitter. Green LED illuminates when correct breaker is located.

POWER ON/OFF

TRANSMITTER

Sends locator signal through outlet wiring. For use on energized circuits.

GFCI TEST

Verifies operation of GFCI protected outlets

INDICATOR LIGHT

LED indicates presence of live voltage on outlet



Southwire™

TOOLS & EQUIPMENT

[BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.]

1-855-SWTOOLS
(855-798-6657)



Southwiretools.com



Features


- Advanced design quickly and reliably pinpoints single breaker without service interruption
- Tests GFCI outlets
- For use on 120V AC energized circuits
- UL Listed

Includes

- 41210S Transmitter and receiver
- 3-prong to 2-prong adapter
- 9V battery

Accessory Kit

- 60030S - Circuit Breaker Adapter Kit for light bulb socket and connection to bare wiring

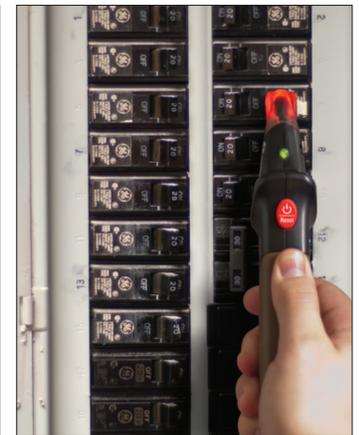

60030S - Adapter Kit

Specifications

Operating Voltage	120V AC
Operating Frequency	50 to 60Hz
Operating Temperature	41° to 140°F (-10° to 60°C)
Storage Temperature	14° to 140°F (-10° to 60°C)
Battery (Receiver)	One 9V
Receiver Dimensions	7.5 x 2.4 x 1.4 in. (191 x 61 x 36mm)
Transmitter Dimension	4.5 x 2.3 x 1.1 in. (114 x 58 x 28mm)

