



LED LINEAR VAPOR TIGHT

SUGGESTED APPLICATIONS

- Commercial
- Industrial
- Production areas
- Stairwells
- Parking garages
- Subway stations

FEATURES

- Meets harsh demands IP66 Rated, IK09 impact rating, NEMA 4x housing
- ETL Sanitation Listed NSF/ANSI Standard 2 - Food Equipment, Splash Zone (Not for Direct Food Zone)
- Stainless-steel latching clips offer easy toolless entry
- Durable UL 5VA flame rated polycarbonate lens and gray housing
- ½" NPT threaded hubs for conduit and cord/bushing entry for continuous end-to-end connection
- Surface mount installation accessories included, J-Box and angle mount kits sold separately
- Available in 4FT, 4000K and 5000K CCT
- Power and CCT Selectable models available in 2', 4', 8' lengths with emergency battery backup and motion sensor options

INPUT VOLTAGE: 120-277V

FREQUENCY: 50/60Hz

POWER FACTOR, THD %:
>0.9, <20%

DIMMABLE: 0-10V,
DOWN TO 10%

EFFICACY: 130 LPW

MINIMUM CRI: 80

FUNCTIONAL LIFE (L70):
50,000 HOURS

LOCATION RATING: WET

AMBIENT OPERATING
TEMPERATURE: -40°F TO 113°F



BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.



LED LINEAR VAPOR TIGHT

ITEM SPECIFICATIONS | ORDER INFO

MODEL #	ORDER CODE	UPC	SIZE (TRADE)	LUMENS	WATTAGE	INPUT CURRENT @120/277V	CCT	DLC ID ¹ STANDARD	DLC ID ² PREMIUM
LVT4-40-40K	73812	032886300615	4'	5,200	40W	0.367/0.159A	4000K	S-9SFPKJ	S-Y3QZVR
LVT4-40-50K	73813	032886300622	4'	5,200	40W	0.367/0.159A	5000K	S-YA39PU	S-CXAUGV

NOMENCLATURE

EXAMPLE: LVT4-40-40K

PRODUCT	SIZE	WATTAGE	CCT
LINEAR VAPOR TIGHT	4'	40W	4000K

ACCESSORIES (SOLD SEPARATELY)

MODEL #	ORDER CODE	UPC	DESCRIPTION
LVT-ANGL-MNT	73821	032886300714	ANGLE MOUNT KIT
LVT-JBOX-MNT	73822	032886300707	J-BOX MOUNT KIT



LVT-ANGL-MNT




LVT-JBOX-MNT

ENERGY SAVINGS *Based on 12 hours/day and \$0.11/kWh*

MODEL #	LED WATTAGE	FLUORESCENT REPLACEMENT WATTAGE	WATTS SAVED	YEARLY SAVINGS	5 YEAR SAVINGS
LVT4-40-XXK	40W	2 x 32W T8	20W	\$10	\$48

DIMENSIONS | WEIGHT

MODEL #	A	B	C	WEIGHT (LBS.)	KNOCKOUTS
LVT4-40-XXK	47.27"	3.74"	3.27"	4.2	(3) 1/2" NPT threaded hubs

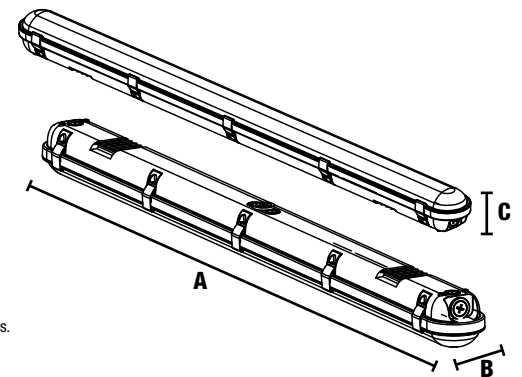

NOTES

¹DLC Primary Use- Standard: Direct Linear Ambient Luminaires

²DLC Primary Use- Premium: Direct Linear Ambient Luminaires

Dimming- Dimming with standard 0-10V control system or wall dimmers. Dimming complies with IEC60929 Annex E. Fixture may not be compatible with all dimmers. Dimming performance may vary based on selected dimmer.

Visit www.topaz-usa.com/led-dimmer-compatibility for up-to-date dimmer compatibility information.

This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

800-666-2852 | TOPAZ-USA.COM

©2022 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.