



# Southwire™

## RIGID CONDUIT NIPPLES

### WITH INSULATED THROAT - ZINC DIE CAST

#### FEATURES

- Corrosion resistant
- Use with locknuts
- Insulated throat protects against abrasion damage

#### APPLICATION

- Serves as a short raceway between enclosures

#### STANDARD MATERIAL

- Zinc die cast

#### CERTIFICATIONS


- UL Standard: UL 514B
- Fed. Spec: W-F-406E, W-F-406D
- NEMA: FB1-2014



752I



PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
751I	1/2"	100	1000	40	.68"	1.02"
752I	3/4"	50	500	30	1"	1.29"
753I	1"	25	250	25	.87"	1.53"
754I	1-1/4"	25	250	35	.94"	1.89"
755I	1-1/2"	25	100	20	.91"	2.30"
756I	2"	10	40	13	1.07"	2.88"
757I	2-1/2"	10	40	17	1.38"	3.39"
758I	3"	10	40	22	1.44"	4.06"
759I	3-1/2"	10	40	27	1.47"	4.61"
760I	4"	5	20	14	1.47"	5.15"

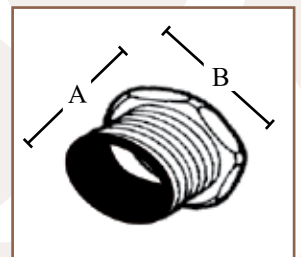

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.