

EVENTER™

THEATRICAL LIFTS

For Lifting Lights & Speakers

The Perfect Lifts for all Venues:


- Changes from operating to stored position in less than five minutes
- Rolls into standard box truck
- All black—no draping needed
- Sturdy construction for operating in windy conditions

Standard Eventer Features:

- Blackened anodized mast
- Fits through standard doorways in stowed position
- No winch cable in operator's face
- Forks reverse for added height
- Large, rubber-padded leveling jacks
- Built-in safety brakes

Great for Outdoor Venues:

- Concerts
- Location filming
- Rallies
- Pageants
- Holiday Events

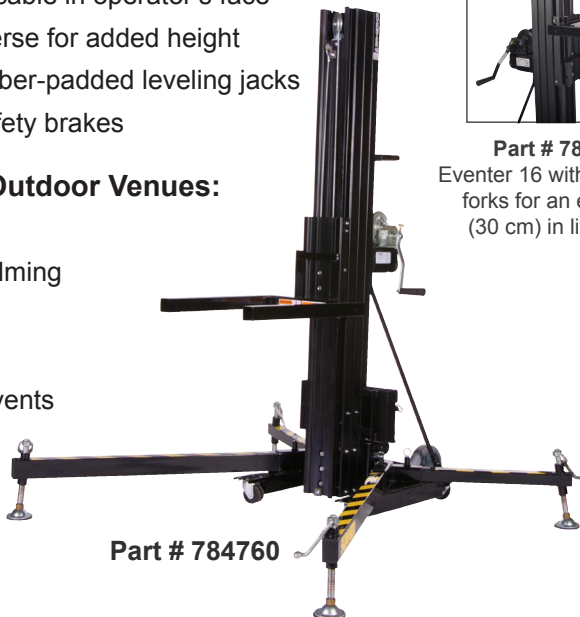

Part # 784760



NEW! Eventer Sound Array Bar

- Easily slides over forks & locks into place.
- Allows single lift point to easily fly Sound Arrays.
- Sizes to fit all models!

EVENTER 16 - Part # 784760
(16' Lift Height / 500 lb. Lift Capacity)

EVENTER 20 - Part # 783801
(20' Lift Height / 800 lb. Lift Capacity)



EVENTER 25 - Part # 783800
(25' Lift Height / 650 lb. Lift Capacity)



Part # 784760
Eventer 16 with reversible forks for an extra 12" (30 cm) in lift height



Part # 784761
Eventer 16 uses Applied adapter (not included)

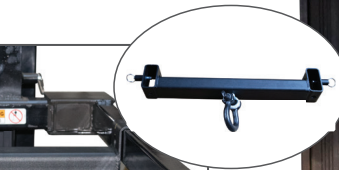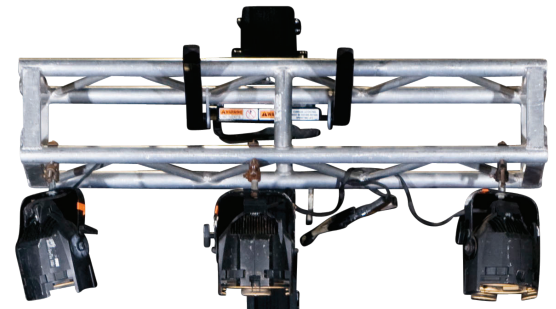

EVENTER Options



Part # 784761
EVENTER 16
Applied Adapter



Part # 784880
EVENTER 16 Boom
has two settings:
355 lbs (155 kg),
400 lbs (180 kg)



Part # 783766
Hook blocks - Attach
sound array hardware

EVENTER Specifications

	EVENTER 16		EVENTER 20		EVENTER 25	
Height (stowed)	78.0"	198.1 cm	78.0"	198.1 cm	78.0"	198.1 cm
Length (stowed)	30.0"	76.2 cm	27.5"	69.2 cm	27.5"	69.2 cm
Width (stowed)	24.5"	62.2 cm	23.0"	58.4 cm	23.0"	58.4 cm
Length (operating)	62.0"	157.5 cm	77.25"	196.2 cm	77.25"	196.2 cm
Width (operating)	67.0"	170.2 cm	75.0"	190.5 cm	75.0"	190.5 cm
Height (forks up)	16' 11.0"	5.15 m	20' 7.75"	6.2 m	25' 2.75"	7.7 m
Height (forks down)	15' 11.0"	4.85 m	18' 8.5"	5.7 m	23' 3.5"	7.1 m
Height (boom -Eventer 16 only)	16' 16.0"	5.03 m				
Ground Clearance	3.75"	9.5 cm	3.25"	8.3 cm	3.25"	8.3 cm
Load Height (min)	5.75"	14.6 cm	8.5"	21.6 cm	8.5"	21.6 cm
Load Center (min)	12.0"	30.5 cm	13.0"	33.0 cm	13.0"	33.0 cm
Load Capacity (at load center)	500.0 lb	225.0 kg	800.0 lb	360.0 kg	650.0 lb	300.0 kg
Lift Weight	279.0 lb	126.8 kg	469.0 lb	215.0 kg	514.0 lb	235.0 kg
Fork Width (min)	19.0"	48.3 cm	16.0"	40.6 cm	16.0"	40.6 cm
Fork Width (max)	19.0"	48.3 cm	25.0"	63.5 cm	25.0"	63.5 cm
Fork Length	23.5"	59.7 cm	28.0"	71.1 cm	28.0"	71.1 cm
Fork Weight	18.0 lb	8.2 kg	41.0 lb	19.0 kg	41.0 lb	19.0 kg
Boom Weight (Eventer 16 only)	14.0 lb	6.4 kg				
Winch Rotation	8 / foot	24 / m	5.25 / ft	17 / m	5.25 / ft	17 / m