




Friendly Service... Powerful Solutions™

# LINEAR FLUORESCENT U-BENT LAMP

## FB031-39

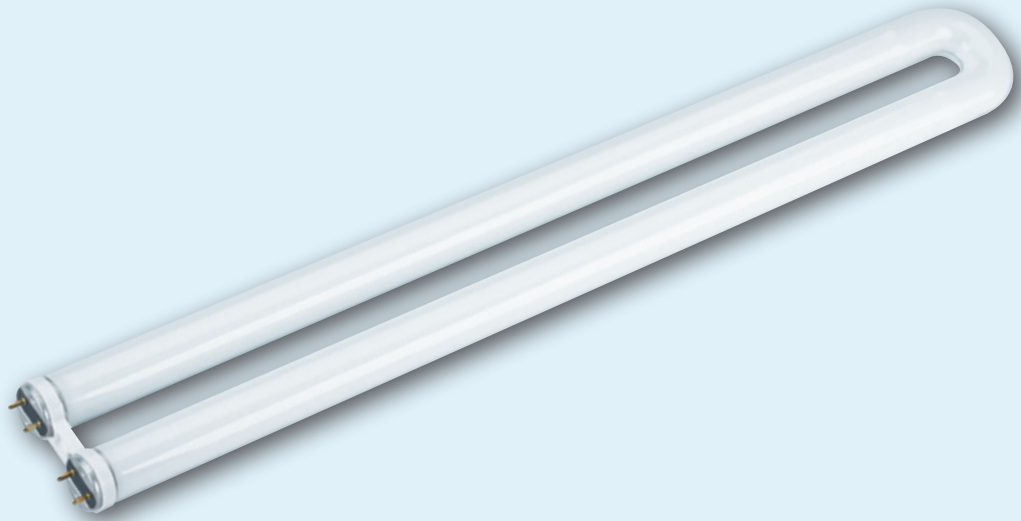

### Specifications

Item #	Watts	CCT	CRI	Lumens	Bulb Shape	Rated Life (HRS)	MOL (IN)	Shape	Base
FB031/3000K-39	31	3000K	85	2700	U-Bent Tube	20,000	22.5	T8U 1 5/8" Spacing	Med Bi-Pin
FB031/3500K-39	31	3500K	85	2700	U-Bent Tube	20,000	22.5	T8U 1 5/8" Spacing	Med Bi-Pin
FB031/4100K-39	31	4100K	85	2700	U-Bent Tube	20,000	22.5	T8U 1 5/8" Spacing	Med Bi-Pin
FB031/5000K-39	31	5000K	85	2700	U-Bent Tube	20,000	22.5	T8U 1 5/8" Spacing	Med Bi-Pin
FB031/6500K-39	31	6500K	85	2700	U-Bent Tube	20,000	22.5	T8U 1 5/8" Spacing	Med Bi-Pin

**TOPAZ LIGHTING™**  
A TOPAZ® COMPANY

[www.topaz-usa.com](http://www.topaz-usa.com)

**NY Office:** 925 Waverly Ave • Holtsville, NY 11742 • 800-666-2852 • Fax: 631-758-8026

**CA Office:** 225 Parkside Drive, San Fernando, CA 91340 • 888-551-2852 or 818-838-3123 • Fax: 888-690-2852 or 818-838-3102

**FL Office:** 2020 West 26th Street, Jacksonville, FL 32209 • 800-338-2852 • Fax: 772-778-5386