



Southwire™

EMT AND RIGID COMBINATION CONDUIT BODIES

LL TYPE

FEATURES

- Combination LL type
- NPT tapered hubs
- Suitable for use in concrete
- NEMA FB 1 rated for wet locations use with threaded rigid metal conduit only

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws

STANDARD FINISH

- Powder coat

CERTIFICATIONS


- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



LL1SS



PART #	SIZE	WIRE SIZE		INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	C
		MAX. NUMBER	MAX. SIZE						
LL1SS	1/2"	1	6 AWG	10	100	28	4.56"	1.31"	2.06"
LL2SS	3/4"	2	6 AWG	10	50	23	5.31"	1.62"	2.23"
LL3SS	1"	3	6 AWG	5	25	18	6.25"	1.88"	2.50"
LL4SS	1-1/4"	3	2 AWG	2	10	14	8.22"	2.50"	3.40"
LL5SS	1-1/2"	3	2 AWG	2	10	16	8.22"	2.67"	3.48"
LL6SS	2"	3	2/0 AWG	---	5	14	10.48"	3.29"	4.07"

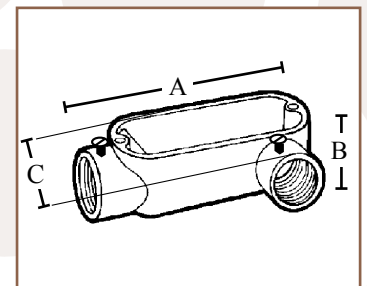

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.