



# Southwire™

## RIGID COUPLINGS

### THREE PIECE TYPE - HOT DIP GALVANIZED - MALLEABLE IRON

#### FEATURES

- For threaded Rigid or IMC conduit
- Hot dip galvanized for superior protection against corrosion

#### APPLICATION

- Use to join two lengths of threaded conduit or IMC when neither can be rotated

#### STANDARD MATERIAL

- Malleable iron

#### STANDARD FINISH

- Hot dip galvanized

#### CERTIFICATIONS

- UL Standard: UL 514B
- RoHS
- Fed. Spec: A-A-50553
- NEMA: FB 1




851HDG



Conforms to finish thickness  
ASTM A123/123M

PART #	SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
851HDG	1/2"	20	200	24	1.36"	1.31"
852HDG	3/4"	10	100	30	1.41"	1.57"
853HDG	1"	5	50	23	1.62"	1.87"
854HDG	1-1/4"	5	50	55	1.83"	2.28"
855HDG	1-1/2"	3	30	44	1.94"	2.59"
856HDG	2"	2	20	44	2.23"	3.14"
857HDG	2-1/2"	---	10	37	3.09"	3.72"
858HDG	3"	---	5	20	3.19"	4.37"
859HDG	3-1/2"	---	5	28	3.37"	4.90"
860HDG	4"	---	2	18	3.45"	5.44"
860AHDG	5"	---	1	9	4.38"	7"
860BHDG	6"	---	1	11	4.38"	8.25"

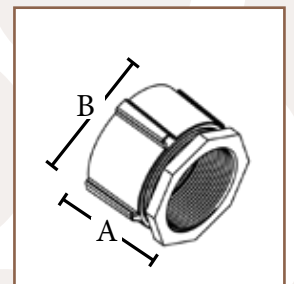

Rev. 0, 03/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.