



# Southwire™

## RIGID LOCKNUTS

### ZINC DIE CAST

#### FEATURES

- Tightens without deformation
- Serrated teeth prevent loosening from vibrations

#### APPLICATIONS

- Affixes Rigid conduit to an electrical box or other metal enclosure
- To connect externally threaded conduit connector to a threadless opening in a box or enclosure

#### STANDARD MATERIAL


- Zinc die cast



241



PART #	SIZE	THREADS PER INCH	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B	THREAD PITCH DIAMETER
241	1/2"	14	200	2000	20	1.12"	.15"	.787 – .797
242	3/4"	14	100	1000	20	1.33"	.15"	.999 – 1.009
243	1"	11-1/2	100	1000	20	1.68"	.19"	1.25 – 1.26
244	1-1/4"	11-1/2	50	500	20	2.15"	.19"	1.595 – 1.605
245	1-1/2"	11-1/2	50	500	20	2.35"	.19"	1.837 – 1.847
246	2"	11-1/2	50	200	12	2.89"	.19"	2.307 – 2.317
247	2-1/2"	8	25	100	13	3.43"	.25"	2.777 – 2.788
248	3"	8	25	100	18	4.12"	.25"	3.403 – 3.414
249	3-1/2"	8	10	40	13	4.67"	.27"	3.892 – 3.904
250	4"	8	10	40	15	5.25"	.27"	4.399 – 4.411

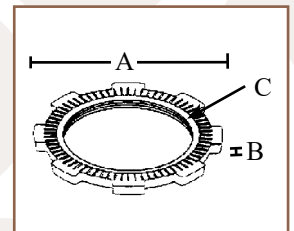

Rev. 0, 05/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.