



Southwire™

EMT CONDUIT BODIES

SET SCREW LB TYPE

FEATURES

- Set screw EMT LB type
- Suitable for use in concrete

APPLICATION

- Provides access to conductors for pulling, splicing and maintenance

STANDARD MATERIAL

- Copper free aluminum die cast
- Steel screws

STANDARD FINISH

- Powder coat


CERTIFICATIONS

- UL Standard: 514A
- Fed. Spec. W-C-586D
- NEMA FB 1



ELB1

| PART # | SIZE | WIRE SIZE | | INNER QTY. | MASTER QTY. | WEIGHT/ CASE (LBS.) | A | B | C |
|--------|--------|----------------|--------------|------------|-------------|------------------------|---------|--------|-------|
| | | MAX. NUMBER | MAX. SIZE | | | | | | |
| ELB1 | 1/2" | 1 | 6 AWG | 10 | 100 | 28 | 4.295" | 2.15" | 1.33" |
| ELB2 | 3/4" | 2 | 6 AWG | 10 | 50 | 19 | 5.09" | 2.43" | 1.54" |
| ELB3 | 1" | 3 | 6 AWG | 5 | 25 | 20 | 5.915" | 2.765" | 1.74" |
| ELB4 | 1-1/4" | 3 | 2 AWG | 2 | 10 | 13 | 7.894" | 3.665" | 2.49" |
| ELB5 | 1-1/2" | 3 | 2 AWG | 2 | 10 | 14 | 7.894" | 3.665" | 2.49" |
| ELB6 | 2" | 3 | 2/0 AWG | 1 | 5 | 13 | 10.134" | 4.275" | 3.10" |
| ELB7 | 2-1/2" | 3 | 2/0 AWG | --- | 1 | 6 | 12.50" | 5.437" | 4.45" |
| ELB8 | 3" | 3 | 4/0 AWG | --- | 1 | 6 | 12.50" | 5.657" | 4.45" |
| ELB9 | 3-1/2" | 3 | 400 MCM | --- | 1 | 8 | 15.50" | 6.922" | 5.50" |
| ELB10 | 4" | 3 | 400 MCM | --- | 1 | 8 | 15.50" | 6.922" | 5.50" |

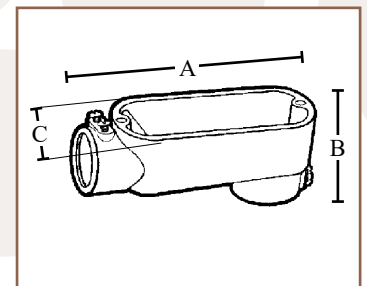

Rev. 0, 02/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.