


# Crossing ETB-TW, bridging, 30°-44°, with jumper, flat profile/tube, TW contact line not auto-tensioned

Item number 100788

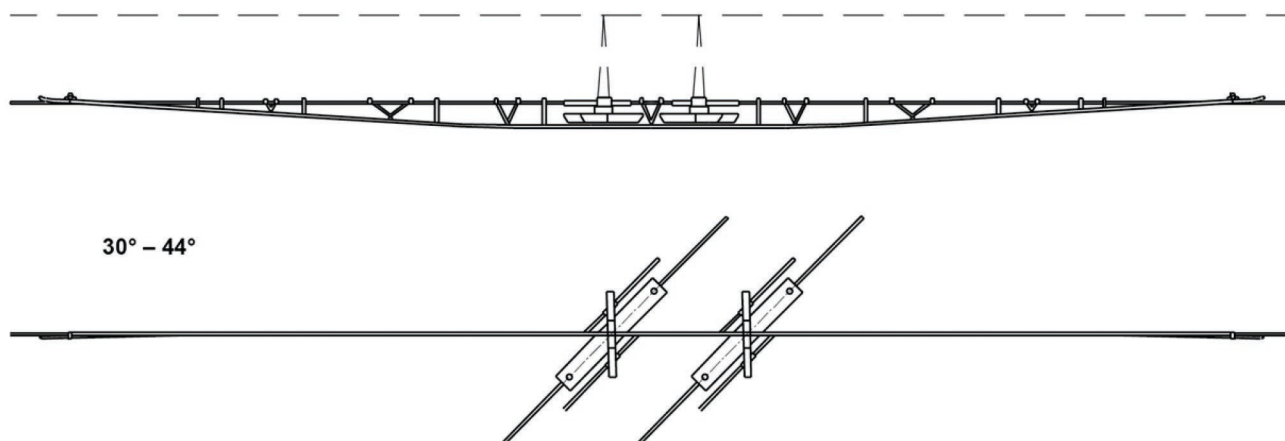

## Specification

Voltage: max. 1000 V DC

## Comments

- For grooved contact wire 80-120 mm<sup>2</sup>

- Without supporting network and suspension
- Execution for 2 TW grooved contact wires on request
- Detailed installation plans can be requested for each delivery of this assembly



**Southwire™**



A COLAS RAIL COMPANY

Contact Us: [Transit@southwire.com](mailto:Transit@southwire.com)