



Southwire™

COMPRESSION LUGS

ONE HOLE - SHORT BARREL

FEATURES

- Ideal for direct burial in earth or concrete and grounding applications
- Produced from high conductivity copper tubing and suitable for heavy duty applications
- Tin-plated to provide corrosion resistance
- Color coded

APPLICATIONS

- Listed for 35 KV maximum when properly installed

STANDARD MATERIAL

- Copper

STANDARD FINISH


- Tin plated



2901



PART #	WIRE SIZE	COLOR CODE	BOLT SIZE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
2901	#8	RED	10	100	1000	14	1.20"	.42"
2901A	#8	RED	1/4"	100	1000	13	1.20"	.42"
2902	#6	BLUE	1/4"	100	1000	17	1.50"	.42"
2902A	#6	BLUE	5/16"	100	1000	17	1.50"	.42"
2903	#4	GRAY	1/4"	100	1000	20	1.50"	.71"
2903A	#4	GRAY	5/16"	100	1000	18	1.50"	.71"
2903B	#4	GRAY	3/8"	100	1000	18	1.50"	.71"
2905	#2	BROWN	3/8"	100	1000	28	1.80"	.83"
2905A	#1	GREEN	3/8"	100	1000	35	1.83"	.67"
2906	1/0	PINK	3/8"	50	500	21	1.83"	.74"
2907	2/0	BLACK	3/8"	50	500	32	2.24"	.81"
2907A	2/0	BLACK	1/2"	50	500	29	2.24"	.81"
2908	3/0	ORANGE	3/8"	25	250	21	2.36"	.90"
2909	4/0	PURPLE	1/2"	25	250	24	2.36"	1"
2909A	250 MCM	YELLOW	1/2"	25	250	30	2.48"	1.09"
2909B	300 MCM	WHITE	1/2"	25	250	33	2.49"	1.19"
2910	350 MCM	RED	1/2"	20	200	33	2.61"	1.28"
2910A	400 MCM	BLUE	1/2"	10	100	24	3.95"	1.39"
2911	500 MCM	BROWN	5/8"	10	100	33	3.28"	1.54"
2911A	600 MCM	GREEN	5/8"	5	50	24	3.50"	1.72"
2912	750 MCM	BLACK	5/8"	5	50	35	4.37"	1.90"

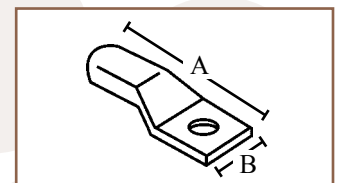

Rev. 0, 10/23

**BUILT FOR DURABILITY.
BUILT FOR RELIABILITY.
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.
*Registered Trademark & ™Trademark of Southwire Company, LLC.