



# Southwire™

## COMPRESSION LUG SPLICES

### SHORT BARREL

#### FEATURES

- Seamless, high conductivity copper tubing, suitable for heavy duty applications
- Tin-plated to provide corrosion resistance
- Color coded

#### APPLICATIONS

- Suitable for use at voltages up to 35 KV provided connector is properly taped
- 5 KV is the maximum voltage in all bare splice applications

#### STANDARD MATERIAL

- Copper


#### STANDARD FINISH

- Tin plated



3301

PART #	WIRE SIZE	COLOR CODE	INNER QTY.	MASTER QTY.	WEIGHT/ CASE (LBS.)	A	B
3301	#8	RED	100	1000	12	.90"	.17"
3302	#6	BLUE	100	1000	14	1"	.20"
3303	#4	GRAY	100	1000	16	1"	.25"
3305	#2	BROWN	100	1000	27	1.25"	.31"
3305A	#1	GREEN	50	500	23	1.60"	.39"
3306	1/0	PINK	50	500	26	1.75"	.44"
3307	2/0	BLACK	50	500	29	1.75"	.49"
3308	3/0	ORANGE	50	500	34	1.90"	.55"
3309	4/0	PURPLE	25	250	23	2"	.59"
3309A	250 MCM	YELLOW	25	250	29	2.10"	.66"
3310	350 MCM	RED	20	200	31	2.10"	.70"
3310A	400 MCM	BLUE	10	100	21	2.30"	.76"
3311	500 MCM	BROWN	10	100	29	2.50"	.83"
3311A	600 MCM	GREEN	5	50	20	2.50"	.93"
3312	750 MCM	BLACK	5	50	29	3.21"	1.03"

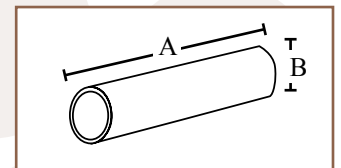

Rev. 0, 10/23

**BUILT FOR DURABILITY.  
BUILT FOR RELIABILITY.  
BUILT FOR WORK.™**

1-855-798-6657 | SOUTHWIRE.COM

©2023 Southwire Company, LLC. All rights reserved.  
\*Registered Trademark & ™Trademark of Southwire Company, LLC.